


# AkroBins®

- Multiple sizes and colors allow **color coding** (vertically and horizontally) and **easy identification** of supplies
- Molded of industrial-grade polymers
- Bins sit on shelves or hang from Akro-Mils panels, racks, rails and carts
- AkroBins stack securely to optimize shelf space
- Bins feature wide hopper fronts for easy access
- Available in 12 colors including Clear



**Kanban Extended Label Holder** with orange flag to show bin needs restocked (see page 20)

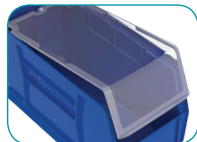

"See-through" clear **bin lids** protect contents



Crystal clear **length dividers**



Large **front label slot** for easy coding and scanning



**Lengthwise dividers** keep items separated



**AWS143630250G**  
AkroBin Wire System



**30230BLUE**



**New 30237** fits perfectly on 18" deep shelving for a two-bin Kanban system



**30224SCLAR**



**30210YELLO**

**30220PURPL**

**30230GREEN**

**30239LTBLU**

**30235BLUE**

**30240STONE**

AkroBins Model No.	Outside Dimensions (In.)			Capacity/Quantity		Accessories					
	L	W	H	Bin Load Cap. On Rack	Bin Ctn. Qty.	Black Length Dividers**	Clear Length Dividers**	Width Dividers**	Divider Pkg. Qty.	Bin Lids***	Lid Pkg. Qty.
<b>30210*</b>	5-3/8	4-1/8	3	10 lbs.	24	<b>40210 (1)</b>	<b>40210CRY (1)</b>	–	6	<b>30211CRY</b>	24
<b>30220*</b>	7-3/8	4-1/8	3	10 lbs.	24	<b>40220 (1)</b>	<b>40220CRY (1)</b>	–	6	<b>30221CRY</b>	24
<b>30237</b>	9-1/4	6	5	20 lbs.	12	<b>40237 (1)</b>	<b>40237CRY (1)</b>	–	6	–	–
<b>30224*</b>	10-7/8	4-1/8	4	20 lbs.	12	<b>40224 (1)</b>	<b>40224CRY (1)</b>	–	6	<b>30225CRY</b>	12
<b>30230**</b>	10-7/8	5-1/2	5	30 lbs.	12	<b>40230 (1)</b>	<b>40230CRY (1)</b>	<b>41230 (3)</b>	6	<b>30231CRY</b>	12
<b>30234**</b>	14-3/4	5-1/2	5	50 lbs.	12	<b>40234 (1)</b>	<b>40234CRY (1)</b>	–	6	–	–
<b>30239**</b>	10-3/4	8-1/4	7	50 lbs.	6	<b>40239 (1)</b>	<b>40239CRY (1)</b>	–	6	–	–
<b>30240**</b>	14-3/4	8-1/4	7	60 lbs.	12	<b>40245 (1)</b>	<b>40245CRY (1)</b>	–	6	–	–
<b>30265</b>	18	8-1/4	9	60 lbs.	6	<b>40265 (1)</b>	<b>40265CRY (1)</b>	–	6	–	–
<b>30235*</b>	10-7/8	11	5	50 lbs.	6	<b>40230 (3)</b>	<b>40230CRY (3)</b>	–	6	<b>30236CRY</b>	6
<b>30260</b>	18	11	10	60 lbs.	6	<b>40260 (3)</b>	<b>40260CRY (3)</b>	–	6	–	–
<b>30255</b>	10-7/8	16-1/2	5	60 lbs.	6	<b>40230 (3)</b>	<b>40230CRY (3)</b>	–	6	–	–
<b>30250**</b>	14-3/4	16-1/2	7	75 lbs.	6	<b>40245 (3)</b>	<b>40245CRY (3)</b>	–	6	–	–
<b>30270</b>	18	16-1/2	11	75 lbs.	3	<b>40270 (3)</b>	<b>40270CRY (3)</b>	–	6	–	–
<b>30320</b>	8-5/8	33	5	80 lbs.	4	<b>40321 &amp; 40220 (7)</b>	<b>40220CRY (7)</b>	–	7	<b>30321</b>	4

One color per carton: Specify Red, Blue, Yellow, Stone, Clear, Green or Black. Order in carton quantities. CAUTION: When using bins with hanging systems, do not exceed the weight capacity for the rack, which may be less than the total sum of bin capacities. 40321=Full Divider; 40220=Short Divider. \*Available in Specialty Colors: Purple and Light Blue. #Available in Hunter Green, Sandstone and Terra Cotta. \*\*() = Max. # of dividers per bin. \*\*\*Assembly required – 30211CRY replaces 30211; 30221CRY replaces 30221; 30231CRY replaces 30231; 30236CRY replaces 30236.

AkroBin Wire Systems			Shelf Dimensions (In.)			Quantity	
Model No.	Description	AkroBin Colors	D	L	H	# of Bins	Shelves
<b>AWS143630320</b>	Wire Shelving w/ 30320 Bins	B, R, Y, G, S, BK, SC	14	36	74	12	11
<b>AWS143630240</b>	Wire Shelving w/ 30240 Bins	B, R, Y, G, S, BK, SC	14	36	74	36	4
<b>AWS143630250</b>	Wire Shelving w/ 30250 Bins	B, R, Y, G, S, BK, SC	14	36	74	18	4
<b>AWS184830260</b>	Wire Shelving w/ 30260 Bins	B, R, Y, G, S, BK, SC	18	48	74	24‡	6
<b>AWS183630265</b>	Wire Shelving w/ 30265 Bins	B, R, Y, G, S, BK, SC	18	36	74	18	5
<b>AWS183630270</b>	Wire Shelving w/ 30270 Bins	B, R, Y, G, S, BK, SC	18	36	74	9‡	5

Bin color code: R=Red, B=Blue, Y=Yellow, G=Green, S=Stone, BK=Black, SC=Clear. Specify one bin color when ordering. †Bonus bins included.

