


Raised Profile Labels - Engraved Plate Substitutes (B-593) Push Button Style

Costs up to 80% less than engraved legend plates.

- High gloss, polyester label with thick raised profile and ultra-aggressive adhesive (0.70mm thick)
- High performance, low cost substitute to engraved plates
- 10-year outdoor durability rating
- On-demand labeling: labels print out in less than 4 seconds
- 5 push button sizes (including keyed and non-keyed 22.5mm, and 30.5mm hole diameter keyed)

Service temp: -4°F to 212°F Application temp: 50°F to 212°F
Average Outdoor Durability: Up to 10 years
Agency approvals:

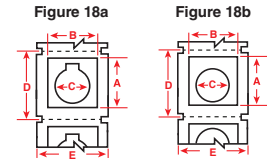

Fits Printer Model(s)	Diagram	Catalog #	Color	Hole Diameter C Inch (mm)	Label Height A Inch (mm)	Label Width B Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
BBP31, BBP33	Fig. 18a	B30EP-167-593-BK	Black	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-167-593-GN	Green	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-167-593-RD	Red	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-167-593-WT	White	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-167-593-YL	Yellow	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
BBP31, BBP33	Fig. 18b	B30EP-167U-593-BK	Black	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
BBP31, BBP33	Fig. 18b	B30EP-167U-593-GN	Green	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
BBP31, BBP33	Fig. 18b	B30EP-167U-593-RD	Red	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R4400-WT
BBP31, BBP33	Fig. 18b	B30EP-167U-593-WT	White	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
BBP31, BBP33	Fig. 18b	B30EP-167U-593-YL	Yellow	0.885 (22.5)	1.500 (38.1)	1.200 (30.5)	1.750 (44.5)	2.500 (63.5)	1	200	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-168-593-BK	Black	0.885 (22.5)	1.900 (48.3)	1.200 (30.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-168-593-GN	Green	0.885 (22.5)	1.900 (48.3)	1.200 (30.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-168-593-RD	Red	0.885 (22.5)	1.900 (48.3)	1.200 (30.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-168-593-WT	White	0.885 (22.5)	1.900 (48.3)	1.200 (30.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-168-593-YL	Yellow	0.885 (22.5)	1.900 (48.3)	1.200 (30.5)	2.125 (54.0)	2.500 (63.5)	1	180	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-169-593-BK	Black	1.200 (30.5)	1.800 (45.7)	1.800 (45.7)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-169-593-GN	Green	1.200 (30.5)	1.800 (45.7)	1.800 (45.7)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-169-593-RD	Red	1.200 (30.5)	1.800 (45.7)	1.800 (45.7)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-169-593-WT	White	1.200 (30.5)	1.800 (45.7)	1.800 (45.7)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-169-593-YL	Yellow	1.200 (30.5)	1.800 (45.7)	1.800 (45.7)	2.000 (50.8)	2.500 (63.5)	1	190	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-170-593-BK	Black	1.200 (30.5)	2.400 (60.9)	2.400 (60.9)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-170-593-GN	Green	1.200 (30.5)	2.400 (60.9)	2.400 (60.9)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-170-593-RD	Red	1.200 (30.5)	2.400 (60.9)	2.400 (60.9)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R4400-WT
BBP31, BBP33	Fig. 18a	B30EP-170-593-WT	White	1.200 (30.5)	2.400 (60.9)	2.400 (60.9)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R6000
BBP31, BBP33	Fig. 18a	B30EP-170-593-YL	Yellow	1.200 (30.5)	2.400 (60.9)	2.400 (60.9)	2.625 (66.7)	3.250 (82.6)	1	145	B30-R6000



Calculate Your Cost Savings

A 1" x 2" rectangular raised profile label costs approximately \$0.60, lasts up to 10 years outdoors and prints in seconds! A 22.5mm push button label will cost you about \$0.32!

What are you paying for engraved plates?

