

HIGH SPEED STEEL DRILL BITS



HIGH SPEED STEEL 118 DEGREE "JOBBER" DRILL BITS




CATALOG# SIZE PCS/PKG CATALOG# SIZE PCS/PKG

91597	1/64	12	91614	17/64 *	12
91599	1/32	12	91615	9/32 *	12
91600	3/64	12	91616	19/64 *	6
91601	1/16 *	12	91617	5/16 *	6
91602	5/64 *	12	91618	21/64 *	6
91603	3/32 *	12	91619	11/32 *	6
91604	7/64 *	12	91620	23/64 *	6
91605	1/8 *	12	91621	3/8 *	6
91606	9/64 *	12	91622	25/64 *	6
91607	5/32 *	12	91623	13/32 *	6
91608	11/64 *	12	91624	27/64 *	6
91609	3/16 *	12	91625	7/16 *	6
91610	13/64 *	12	91626	29/64 *	6
91611	7/32 *	12	91627	15/32 *	6
91612	15/64 *	12	91628	31/64 *	6
91613	1/4 *	12	91629	1/2 *	6

TO ORDER NEW SET-UP OF COMPLETE DISPLAY - ORDER ONE PACKAGE QUANTITY OF EACH * SIZE AND ONE #91808 EMPTY COUNTER DISPLAY.

91808

EMPTY COUNTER DISPLAY

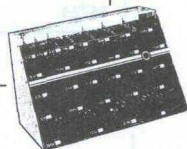

HEAVY DUTY "JOBBER" DRILLS

135 DEGREE SPLIT POINT



CATALOG# SIZE PCS/PKG CATALOG# SIZE PCS/PKG

91901	1/16 *	12	91916	19/64 *	6
91902	5/64 *	12	91917	5/16 *	6
91903	3/32 *	12	91918	21/64 *	6
91904	7/64 *	12	91919	11/32 *	6
91905	1/8 *	12	91920	23/64 *	6
91906	9/64 *	12	91921	3/8 *	6
91907	5/32 *	12	91922	25/64 *	6
91908	11/64 *	12	91923	13/32 *	6
91909	3/16 *	12	91924	27/64 *	6
91910	13/64 *	12	91925	7/16 *	6
91911	7/32 *	12	91926	29/64 *	6
91912	15/64 *	12	91927	15/32 *	6
91913	1/4 *	12	91928	31/64 *	6
91914	17/64 *	12	91929	1/2 *	6
91915	9/32 *	12			



Cully