
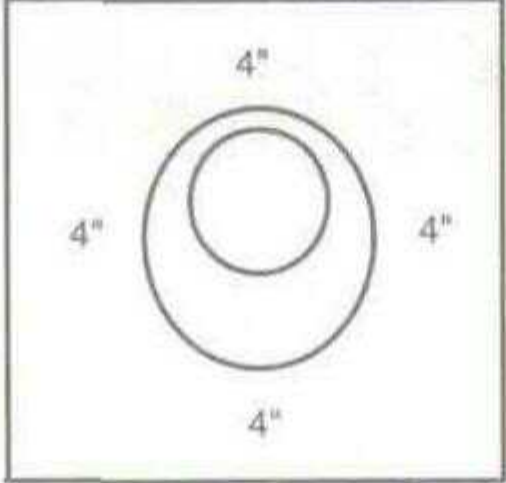
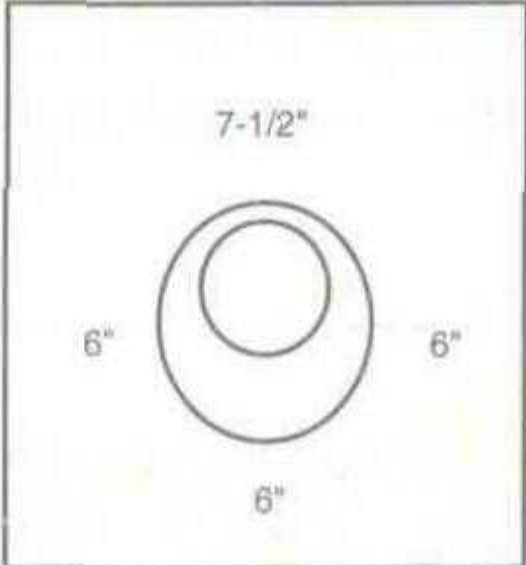


PC 5220		Conduit Hangers w/Bolts				Zinc Plated	Hangers Flashings
Cat. No.	UPC	Trade Size	Pipe	E.M.T.	Bolt Size	Unit	
PH50B	28320	0B	3/8-1/2"	1/2"	1/4-20 X 1	100	
PH75B	28322	1B	3/4"	3/4"	1/4-20 X 1-1/4	100	
PH100B	28324	2B	1"	1"	1/4-20 X 1-1/4	100	
PH110B	28326	2-1/2B	—	1-1/4"	1/4-20 X 1-1/4	100	
PH125B	28328	3B	1-1/4"	1-1/2"	1/4-20 X 1-1/4	100	
PH150B	28330	4B	1-1/2"	—	1/4-20 X 1-1/2	100	
PH200B	28332	5B	2"	2"	1/4-20 X 1-1/2	50	
PH250B	28334	6B	2-1/2"	2-1/2"	1/4-20 X 1-1/2	50	
PH300B	28336	7B	3"	3"	1/4-20 X 1-1/2	25	
PH350B	28337	8B	3-1/2"	—	1/4-20 X 2	25	
PH400B	28338	9B	4"	—	1/4-20 X 2	25	

PC 5230		Standard	Roof Jacks (Flashings)	28 Gauge		
Cat. No.	UPC			Pipe Size	Unit	
RJ50	69600			1/2"	24	
RJ75	69605			3/4"	24	
RJ100	69610			1"	24	
RJ125	69615			1-1/4"	24	
RJ150	69620			1-1/2"	24	
RJ200	69625			2"	24	
*RJ300	69630			3"	12	
*RJ400	69635			4"	12	
*Broken Quantity Add 10%.						

PC 5240		F.H.A.	Roof Jacks (Flashings)	28 Gauge		
Cat. No.	UPC			Pipe Size	Unit	
FHA50	69650			1/2"	24	
FHA75	69655			3/4"	24	
FHA100	69660			1"	24	
FHA125	69665			1-1/4"	24	
FHA150	69670			1-1/2"	24	
FHA200	69675			2"	24	
*FHA300	69680			3"	12	
*FHA400	69685			4"	12	
*Broken Quantity Add 10%.						

PC 5250		3 in 1 Roof Jack (Flashings)		
Galvanized Base Roof Flashings 24 GA with Elastomer Collar				
Cat. No.	UPC	Description	Std.	
RN3	10350	Pipe Sizes: 1/2", 3/4", 1"* Base Size: 8-3/4" x 12-1/2"	12	
RN4	10352	Pipe Sizes: 1-1/2", 2", 3" Base Size: 10-3/4" x 12-1/2"	12	
* Can be modified to fit 1-1/4" pipe				
<ul style="list-style-type: none"> • Fits any roof pitch— from flat to 45° • Tested for ultraviolet, ozone, and weather resistance 				

