

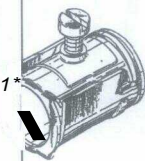


PC 5660	Steel	Locknuts		Zinc Plated	Fittings
Cat. No.	UPC	Size	Unit	Std.	
LN38	12300	3/8"	100	1000	
LN50	12301	1/2"	100	1000	
LN75	12302	3/4"	100	1000	
LN100	12303	1"	100	500	
LN125	12304	1-1/4"	50	250	
LN150	12305	1-1/2"	50	250	
LN200	12306	2"	50	100	
LN250	12307	2-1/2"	25	100	
LN300	12308	Y	25	100	
LN350	12309	3-1/2"	25	50	
LN400	12310	4"	25	50	
LN500	12311	Y	10	10	
LN600	12312	6"	10	10	

PC 5670	Plastic Bushings		105° C		
Cat. No.	UPC	Size	Unit	Std.	
PB50	10100	1/2"	100	1000	
PB75	10105	3/4"	100	1000	
FBI100	10110	1"	50	500	
PB125	10115	1-1/4"	25	250	
PB150	10120	1-1/2"	25	250	
PB200	10125	2"	25	250	
PB250	10130	2-1/2"	25	100	
PB300	10135	3"	25	100	
PB350	10140	3-1/2"	10	50	
PB400	10145	4"	10	20	
PB500	10150	5"	10	10	
PB600	10155	6"	10	10	

PC 552	AC/MC Connectors				
Cat. No.	UPC	Description	Unit	Std.	
APC-5)	15600	14/2 Thru 10/3 AC or MC 3/8" Flexible Metal Conduit (Steel or Aluminum) Size: To fit 1/2" knockout. "SAFETY LOCK" AC/MC CONNECTORS	50	500	
<ul style="list-style-type: none"> • All steel — one piece body including saddle. • Installs in seconds, from outside of the box, for large labor saving. • No need to reach into live, hot areas to put on or tighten locknuts. • Smooth, Insulated throat for easy wire pull and no wire abrasion • Simply tightening the screw locks the connector into the box or panel, and onto the conduit. • To install the straight connector, tilt, and snap in. Tighten screw onto conduit and installation is complete. • Reuseable. 					