


# LS Series Dimmers

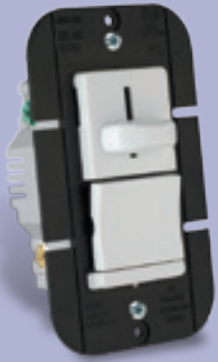

## \*COLOR DESIGNATION

<b>W</b>	White
<b>LA</b>	Light Almond
<b>I</b>	Ivory
<b>BK</b>	Black
<b>-</b>	Brown



PART NO.	DESCRIPTION	COLOR	RATING
LS1000*	<b>Incandescent</b> Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120V, 1000W
LS1000P*	<b>Incandescent</b> Single Pole, Preset		
LS1003P*	<b>Incandescent</b> 3-Way, Preset		
LS600*	<b>Incandescent</b> Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120V, 600W
LS600LWV	<b>Incandescent</b> Lighted, Single Pole, Non-Preset	White	
LS600P*	<b>Incandescent</b> Single Pole, Preset	Black, Brown, Ivory, Light Almond, White	
LS603P*	<b>Incandescent</b> 3-Way, Preset		
LS603PLWV	<b>Incandescent</b> Lighted, 3-Way, Preset	White	
LSCL450*	<b>CFL/LED/Incandescent</b> Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120VAC, 450W, CFL/LED; 700W Incandescent
LSCL453P*	<b>CFL/LED/Incandescent</b> 3-Way, Preset		
LSCLDC163P*	<b>CFL/LED/Incandescent</b> Single Pole/3-Way, Preset, Dimmer with Single Pole/3-Way, 3-Speed De-hummer Fan Control	Black, Brown, Ivory, Light Almond, White	1.6A, (Fan Control); 120VAC, 150W CFL/LED; 300W Incandescent (Dimmer)
LSLV600*	<b>Magnetic Low Voltage</b> Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120V, 600VA
LSLV600P*	<b>Magnetic Low Voltage</b> Single Pole, Preset		
LSLV603P*	<b>Magnetic Low Voltage</b> 3-Way, Preset		
LSDC16V*	<b>Fan Speed Control</b> 3-Speed De-hummer Fan Speed Control, Non-Preset with Single Pole Incandescent Dimmer	Brown, Ivory, Light Almond, White	1.6A, (Fan Control); 120V; 300W Incandescent (Dimmer)
LSDC16PV*	<b>Fan Speed Control</b> 3-Speed De-hummer Fan Speed Control, Preset with Single Pole Incandescent Dimmer	Brown, Black	
LSDH16V*	<b>Fan Speed Control</b> 4-Speed De-hummer, Non-Preset	Black, Brown, Ivory, Light Almond, White	1.6A
LSSC5*	<b>Fan Speed Control</b> Single Pole with Adjustable Trim, Non-Preset		5A
LSSC5P*	<b>Fan Speed Control</b> Single Pole with Adjustable Trim, Preset		

All devices are US LISTED.

# DR Series Dimmers

 


PART NO.	DESCRIPTION	COLOR	RATING
DRCL453P*	<b>CFL/LED</b> Single Pole/3-Way, Preset <i>Available Spring 2016</i>	Black, Brown, Ivory, Light Almond, White	120V, 450W, CFL/LED; 700W, Incandescent
DR703P*V	<b>Incandescent</b> Single Pole/3-Way with Pilot Light, Preset	Black, Brown, Ivory, Light Almond, White	120V, 700W
DRLV1103P*	<b>Magnetic Low Voltage</b> Single Pole/3-Way with Pilot Light, Preset	Black, Brown, Ivory, Light Almond, White	120V, 1100VA
DRLV703P*			120V, 700VA
DRDH163P*V	<b>Fan Speed Control</b> 3-Speed De-hummer Fan Speed Control with Single Pole/3-Way, Backlit Speed Indication, Preset	Black, Brown, Ivory, Light Almond, White	120V, 1.6A
DRSC53P*V	<b>Fan Speed Control</b> Continuously Variable, Single Pole/3-Way, Preset		120V, 5A

All devices are cUL<sup>®</sup> US LISTED.

#### \*COLOR DESIGNATION

<b>W</b>	White
<b>LA</b>	Light Almond
<b>I</b>	Ivory
<b>BK</b>	Black
<b>-</b>	Brown



# Rotary Series Dimmers



PART NO.	DESCRIPTION	COLOR	RATING
R1000*V	<b>Incandescent</b> Single Pole with RFI Filtering, Non-Preset	Ivory, Light Almond, White	120V, 1000W
R1000P*V	<b>Incandescent</b> Single Pole with RFI Filtering, Preset		
R1003P*V	<b>Incandescent</b> 3-Way with RFI Filtering, Preset		
R600*V	<b>Incandescent</b> Single Pole with RFI Filtering, Non-Preset	Ivory, Light Almond, White	120V, 600W
R600P*V	<b>Incandescent</b> Single Pole with RFI Filtering, Preset		
R600PLTKV	<b>Incandescent</b> Single Pole with RFI Filtering, Preset	Three Interchangeable Face Colors: Ivory, White, Light Almond	
R603P*V	<b>Incandescent</b> 3-Way with RFI Filtering, Preset	Ivory, Light Almond, White	
R603PLTKV		Three Interchangeable Face Colors: Ivory, White, Light Almond	

All devices are cUL<sup>®</sup> US LISTED.

 
# Toggle Dimmers



PART NO.	DESCRIPTION	COLOR	RATING
T1000*	<b>Incandescent</b> Single Pole, Non-Preset	Brown, Ivory, Light Almond, White	120V, 1000W
T1003*	<b>Incandescent</b> 3-Way, Non-Preset		
T600*	<b>Incandescent</b> Single Pole, Non-Preset	Brown, Ivory, Light Almond, White	120V, 600W
TLV603*	<b>Magnetic Low Voltage</b> 3-Way, Non-Preset	Ivory, Light Almond, White	120V, 600VA
TD1103P*	<b>Incandescent</b> Single Pole/3-Way, Preset	Black, Brown, Ivory, Light Almond, White	120V, 1100W
TD703P*			120V, 700W
TDFB83P*	<b>Fluorescent</b> Single Pole/3-Way, Two Wire, Preset	Black, Brown, Ivory, Light Almond, White	120V, 8A
TSC5*	<b>Fan Speed Control</b> Adjustable Trim, Non-Preset	Ivory, Light Almond, White	120V, 5A
TDDH163P*	<b>Fan Speed Control</b> De-hummer	Black, Brown, Ivory, Light Almond, White	120V, 1.6A
TDCL453P*	<b>CFL/LED</b> Single Pole/3-Way, Preset <i>Available Spring 2016</i>	Black, Brown, Ivory, Light Almond, White	120V, 450W, CFL/LED; 700W, Incandescent

## \*COLOR DESIGNATION

<b>W</b>	White
<b>LA</b>	Light Almond
<b>I</b>	Ivory
<b>BK</b>	Black
<b>-</b>	Brown



All devices are US LISTED.

## A SMOOTH, SEAMLESS ACCENT FOR ANY DÉCOR



### SCREWLESS WALL PLATES

- Premium finishes that stand up to constant use
- Hidden screws create a sleek, seamless accent
- Available in single- and multiple-gang