


Storage Boxes

For storage and security think of Greenlee storage boxes first. Welded 16 gauge steel construction with overlapping corners, rolled edges and strategically placed reinforcement make these boxes strong and rigid. Most models feature patented recessed and concealed dual lock protectors which protect locks from tampering and weather. All models feature continuous non-removable pin hinges to deter theft.

Overlapping rolled edge lids and doors help keep the contents safe and secure. Built-in skids with holes for mounting optional casters allows for easy moving both on casters or with material handling equipment. The boxes are then finished inside and out with a durable baked enamel finish.


Small Storage Boxes

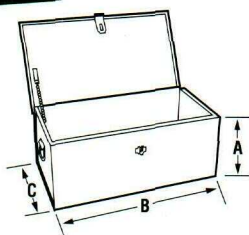

- Protects small tools and supplies. Single lock hasp for use with padlock.
- Compact side handles for easy portability.
- Heavy-duty hinges plus chain connector to hold lid in open position.

Cat. No.	UPC No.	Capacity		Dimensions			Weight	
		ft ³	m ³	A in. (mm)	B in. (mm)	C in. (mm)	lbs.	kg
1230	31510	3.3	.09	12 (305)	30 (762)	16 (406)	48	21.8
1531	23274	4.5	.13	15 (381)	31 (787)	18 (457)	51	23.1

Mobile Storage Boxes

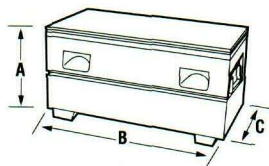

CASTERS NOT INCLUDED

- Easy mobility for jobsite or shop use.
- Dual recessed and concealed lock protectors for maximum security against drilling and cutting lock.
- Built-in skids with holes for easy caster installation.
- Large fold-down recessed handles for convenient lifting.
- Heavy-duty piano hinges with nonremovable pin.
- Steel support arms to hold lid in open position.
- Convenient storage tray on back wall for small items (except Model 1332).
- Optional casters are available separately for easy mobility.

Cat. No.	UPC No.	Capacity		Dimensions			Weight	
		ft ³	m ³	A in. (mm)	B in. (mm)	C in. (mm)	lbs.	kg
1332	38717	4.9	.14	14 (356)	32 (813)	19 (483)	83	37.6
1636	38718	6.7	.19	17 (432)	36 (914)	19 (483)	99	44.9
2142	31651	9.7	.27	20 (508)	42 (1067)	20 (508)	113	51
2448	23273	16	.45	24 (610)	48 (1219)	24 (610)	146	66
2460	23363	20	.57	24 (610)	60 (1524)	24 (610)	182	83
3048	23362	25	.71	30 (762)	48 (1219)	30 (762)	183	83

OPTIONAL ACCESSORIES - CASTERS

Cat. No.	UPC No.	Description	Wheel		Capacity per Wheel		Ship Weight	
			Dia. in. (mm)	Tread in. (mm)	lbs.	kg	lbs.	kg
666	15341	2 Rigid, 2 Swivel	4 (102)	2 (51)	400	181	13	6
695	30239	2 Rigid, 2 Swivel	4 (102)	2 (51)	375	170	10	5
694	35113	4 Swivel	4 (102)	2 (51)	400	181	13	6