



**MCR
SAFETY**

9370M

Cut Protection Specification Sheet

PRODUCT DESCRIPTION:

Kevlar® string knit gloves are used for general purpose work applications to provide cut and abrasion resistance, using high performance yarns, to further protect the hands when working with sharp objects. Various material weights provide longer durability or additional dexterity where needed. The 9370 features a 7 gauge regular weight 100% Dupont™ Kevlar® string knit material. It has a plain shell.

FEATURES:

- 7 gauge 100% Dupont™ Kevlar® Fibers
- Plain shell
- Regular weight


APPLICATIONS:

Assembly Line Production, Carpentry, Construction, Demolition, Farming, Furniture industry, Landscaping, Manufacturing, Metal fabrication, Recycling, Salvage



TECHNICAL DATA FOR: 9370M

Material Group	Strings	ANSI Cut	ANSI Cut A3
Product Type	Cut Protection	ANSI Contact Heat	Level 3 (Applications less than 392 degrees F)
Glove Size	Medium		
Gauge	7 Gauge		
Material	Kevlar		
Made In	Mexico		

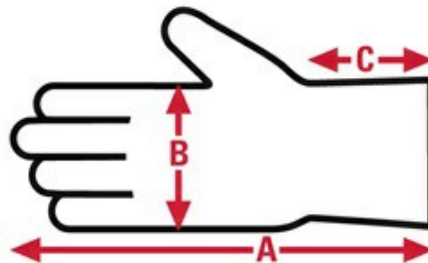

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2019 MCR Safety - All Rights Reserved



MCR
SAFETY

9370M

**Cut Protection
Specification Sheet**

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9370M	Medium	9.50	3.75	N/A	17.376 lb.	1.448

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2019 MCR Safety - All Rights Reserved