

Straight Blade Devices Decorator Receptacles

2 Pole, 3 Wire Grounded 15 & 20A, 125 & 250V

Pass & Seymour
legrand


Straight Blade Devices

Features - Hospital & Specification Grade


- Impact-resistant nylon face.
- One-piece, triple-wipe brass power contacts.
- Corrosion resistant, plated, wrap-around steel strap locked into assembly to prohibit strap from bending away from body.
- Terminal compartments isolated from each other for positive conductor containment.
- Available in hospital grade & specification grade.
- Heavy-duty compact design for easier installation & long lasting performance.
- Automatic grounding clip standard for positive ground to metal boxes.
- All devices fit standard #26 opening wall plate.
- Side & backwire accepts #14 - #10 AWG.

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance		
				UL UL498	FSUL WC596-G	CS C22.2 42M
Hospital Grade Duplex Receptacle Back & Side Wire						
26262-HGI	15 125	Ivory	5-15R	•	•	•
26262-HGW	15 125	White	5-15R	•	•	•
26262-HGRED	15 125	Red	5-15R	•	•	•
26362-HGI	20 125	Ivory	5-20R	•	•	•
26362-HGW	20 125	White	5-20R	•	•	•
26362-HG	20 125	Brown	5-20R	•	•	•
26362-HGGRY	20 125	Gray	5-20R	•	•	•
26362-HGRED	20 125	Red	5-20R	•	•	•
Hospital Grade Isolated Ground Duplex Receptacles Back & Side Wire						
IG26262-HG	15 125	Orange	5-15R	•	•	•
IG26362-HG	20 125	Orange	5-20R	•	•	•
IG26362-HGW	20 125	White	5-20R	•	•	•
Hospital Grade Illuminated Duplex Receptacles Back & Side Wire						
26222-HGI	15 125	Ivory	5-15R	•	•	•
26322-HGI	20 125	Ivory	5-20R	•	•	•
26322-HGGRY	20 125	Gray	5-20R	•	•	•
26322-HGRED	20 125	Red	5-20R	•	•	•


Specification Grade Duplex Receptacles Back & Side Wire						
26252-I	15 125	Ivory	5-15R	•	•	•
26252-W	15 125	White	5-15R	•	•	•
26252	15 125	Brown	5-15R	•	•	•
26252-GRY	15 125	Gray	5-15R	•	•	•
26252-BK	15 125	Black	5-15R	•	•	•
26252-RED	15 125	Red	5-15R	•	•	•
26252-LA	15 125	Lt. Almond	5-15R	•	•	•
26352-I	20 125	Ivory	5-20R	•	•	•
26352-W	20 125	White	5-20R	•	•	•
26352	20 125	Brown	5-20R	•	•	•
26352-GRY	20 125	Gray	5-20R	•	•	•
26352-BK	20 125	Black	5-20R	•	•	•
26352-RED	20 125	Red	5-20R	•	•	•
26352-LA	20 125	Lt. Almond	5-20R	•	•	•

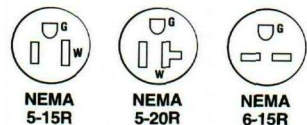


All devices listed on this page conform to NEMA WD-1.

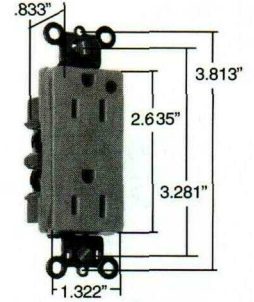


26262-HG Series

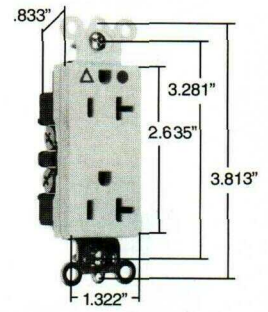

IG 26262-HG Series

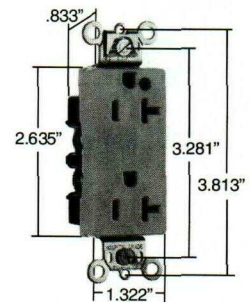

26322-HG Series

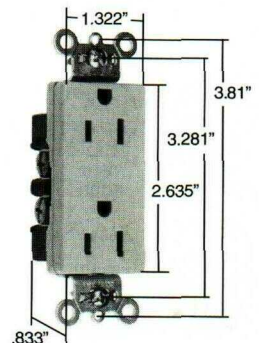

26252 Series

Decorator Receptacles