

Straight Blade Devices Commercial Receptacles Specification Grade


Pass & Seymour
legrand

2 Pole, 3 Wire Grounded 15 & 20A, 125V

Features

- All thermoplastic body construction.
- Impact-resistant nylon face.
- One-piece triple-wipe brass power contact.
- Available with side wiring only & side & back wire models capable of accepting #14 - #10 AWG copper or copper-clad wire.
- Terminal compartments isolated from each other for positive conductor containment.
- Automatic grounding clip assures grounding to metallic boxes.
- Easily accessible break off tabs to facilitate split circuit wiring.
- Plated steel strap for corrosion resistance.
- Combination phillips/slotted head screws backed out for ease of installation.

Catalog Number	Rating		Color	NEMA Config. No.	3rd Party Compliance	
	A.	V.			UL	CS
					UL498	C22.2 42M
Duplex Receptacles Side Wire						
CR15-I	15	125	Ivory	5-15R	•	•
CR15-W	15	125	White	5-15R	•	•
CR15	15	125	Brown	5-15R	•	•
CR15-GRY	15	125	Gray	5-15R	•	•
CR15-LA	15	125	Lt. Almond	5-15R	•	•
CR20-I	20	125	Ivory	5-20R	•	•
CR20-W	20	125	White	5-20R	•	•
CR20	20	125	Brown	5-20R	•	•
CR20-GRY	20	125	Gray	5-20R	•	•
CR20-LA	20	125	Lt. Almond	5-20R	•	•
CR20-BK	20	125	Black - 100 Pk Bulk	5-20R	•	•

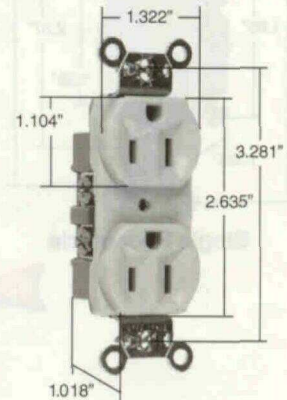

CR/BR Series

Duplex Receptacles Back & Side Wire						
BR15-I	15	125	Ivory	5-15R	•	•
BR15-W	15	125	White	5-15R	•	•
BR15	15	125	Brown	5-15R	•	•
BR15-GRY	15	125	Gray	5-15R	•	•
BR15-LA	15	125	Lt. Almond	5-15R	•	•
BR20-I	20	125	Ivory	5-20R	•	•
BR20-W	20	125	White	5-20R	•	•
BR20	20	125	Brown	5-20R	•	•
BR20-GRY	20	125	Gray	5-20R	•	•
BR20-LA	20	125	Lt. Almond	5-20R	•	•

 


NEMA
5-15R



NEMA
5-20R

All devices listed on this page conform to NEMA WD-1.



Straight Blade Devices

Commercial Receptacles Spec. Grade