


# Blackburn®

## Service Entrance Heads

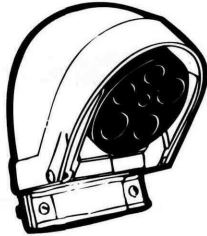

TYPE DEH

- Rugged clamp-on head can be used on EMT without special spacers
- Rigid conduit need not be threaded for installation
- Extra roomy interior simplifies wiring, especially when using maximum size conductors
- Cast of high strength, corrosion resistant aluminum alloy
- Plated steel screws

### Type DEH Aluminum Service Entrance Heads for Rigid Conduit, IMC or EMT

Cat.No.	Conduit Size	Knockouts	
		Qty.	Diameter
DEH12	1/2	4	.297
DEH34	3/4	2	.375
		3	.406
DEH1	1	2	.437
		3	.500
DEH114	1 1/4	2	.422
		3	.625
DEH150	1 1/2	2	.594
		1	.437
		3	.750
DEH2	2	2	.735
		3	.984
		1	.516
DEH250*	2 1/2	3	1.312
		3	.875
		1	1.000
DEH3*	3	4	1.125
		3	1.750
DEH350**	3 1/2	4	1.125
		3	1.750
DEH4**	4	4	1.125
		3	1.750

\* U.L. Listed for rigid conduit only.

\*\* Not U.L. Listed.



TYPE WEH

### Type WEH Reducing Type

Cat. No.	Head Side	Conduit Size	Knockouts	
			Qty.	Diameter
WEH214*	1 1/4	2	2	.422
			3	.625
WEH2150**	1 1/2	2	2	.594
			1	.437
			3	.750
WEH212*	1 1/4	2 1/2	2	.422
			3	.625
WEH252**	2	2 1/2	2	.735
			3	.984
			1	.516

\* U.L. Listed for rigid conduit only.

\*\* Not U.L. Listed.

