


UL File No. E-17909 1/2" - 3/4"  
UL File No. E-1275 1"-3"  
3/8"-3/4"-STEEL

### Straight Connectors

#### Straight Squeeze Type Connectors-Malleable Iron or Stamped Steel / Zinc Plated

Cat. No.	Conduit Size	Unit Qty.	Std. Ctn.
XC-400	3/8" (<2" K.O.)	50	100
XC-401	1/2"	25	100
XC-402	3/4"	25	100
XC-403	1"	25	100
XC-404	1 1/4"	5	10
XC-405	1 1/2"	10	10
XC-406	2"	10	10
XC-407	2W	5	5
XC-408	y	5	5

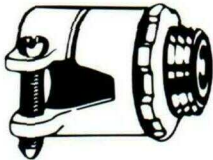


1/2"-3/4"-STEEL

#### Straight Squeeze Type Connectors-Insulated Malleable Iron or Stamped Steel / Zinc Plated

Cat. No.	Conduit Size	Unit Qty.	Std. Ctn.
XC-901	1/2"	25	100
XC-902	3/4"	25	100
XC-903	1"	25	100
XC-904	1 1/4"	5	10
XC-905	1 1/2"	10	10
XC-906	2"	10	10
XC-907	2 1/2"	5	5
XC-908	3"	5	5

### Clamp Straight Set, 90°, and Duplex Connectors

#### 90° Angle Squeeze Type Connectors-Steel or Malleable Iron / Zinc Plated

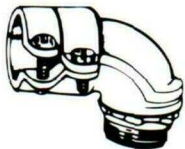

UL File No. E-17909 3/8" & 1/2"  
UL File No. E-1275 1"-3"  
3/8"-1/2"-STEEL

Cat. No.	Conduit Size	Unit Qty.	Std. Ctn.
XC-490	3/8" (W K.O.)	50	100
XC-491	1/4"	25	100
XC-492	3/4"	25	50
XC-493	r	25	25
XC-494	V/i	1-	10
XC-495	1 1/4"	10	10
XC-496	y	5	5
XC-497	254"	1	1
XC-498	3"	1	1

For die cast armored cable/flexible metallic conduit fittings and combination fittings refer to the Steel City Die Cast Conduit Fittings section.