






CTDW

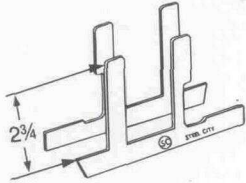


820-D

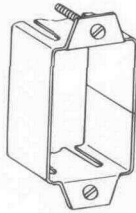

 
SBEX

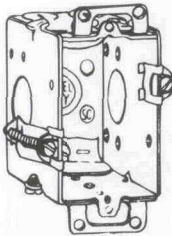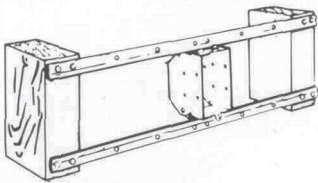

OWC  
• Adapts to any wall thickness up to 3/4"

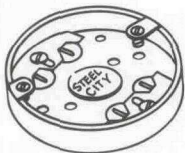

36115-C  
Cover screws  
supplied

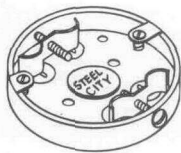

36125-D  
Cover screws  
supplied

### 4" x 2 1/16" Thru-Wall Box

With conduit KOs for plaster or dry wall

Cat. No.	Knockouts	Cu. In. Cap.	Box Depth (in.)	Std. Ctn.
CTDW	Drywall, partition type; One 1/2" and one 3/4" KO both ends; one 1/2" KO on one side, "V" bracket other side	32.0	4 5/16	25

### Switch Box Supports

Cat. No.	Description	Std. Ctn.
820-D	Two metal holders for mounting old-work switch boxes in all types of wall materials (1 1/2" max thickness)	500 sets

### Switch Box Extension

Cat. No.	Description	Std. Ctn.
SBEX	Cubic content 3.5 inches; fits snugly inside of all single gang switch boxes; maximum adjustable depth 1/4"; furnished with 1 1/4" long screws for mounting	50

U.L. Listing not applicable—subject to approval by local inspector.

### Kruse Switch Box Supports

Cat. No.	Description	Length (in.)	Std. Ctn.
8100	Will accommodate any standard switch box with mounting ears—singly or in gangs	16 1/2	50 Pairs
8101	Each set consists of two metal strips; numerous nail holes are provided for fastening regardless of stud spacing	18 1/2	50 Pairs

To Install: Nail lower strip to studding, insert ear of switch box into U-shaped channel, apply upper channel over top ear and nail to studding.

### Old Work Box Support Clips

Cat. No.	Description	Std. Ctn.
OWC	Clips lock old-work steel switch boxes tightly to wall—plaster, drywall, concrete block, brick, or concrete. 2 required per box, (1 set)	250 sets

### 3/4" Round Boxes

Cat. No.	Clamps	Knockouts		Std. Ctn.
		Bottom Conduit	Cable	
<b>1/2" deep—with nonmetallic sheathed cable clamps—4.0 cubic inch capacity</b>				
36115-C-30	C-8	1—1/2"	4	100
<b>3/4" deep—with nonmetallic sheathed cable clamps—5.5 cubic inch capacity</b>				
36125-D	C-10	1—1/2"	4	25