


ELECTRIC BASEBOARD CONVECTION HEATERS

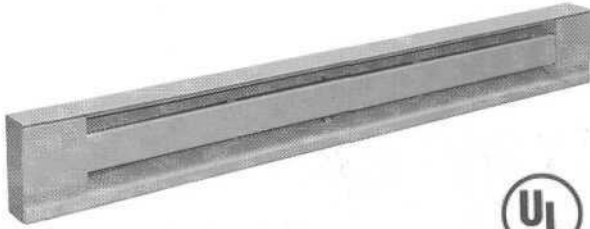


- Available in white or ivory with steel rod heating element and aluminum fins
- Powder coated 22ga. steel front with 20 ga. junction boxes located on each end of the heater - junction boxes contain quick connect cable clamps and 6" ground lead wires
- Over-temperature thermal limit extends entire length of heated area
- A full length wireway provided along the back of the heater
 - optional wireway covers are available
- Heater can be mounted to the wall by using the key hole knockouts every 4" at the back of the heater
- Optional built-in thermostats install in the junction box covers
- HEIGHT - 6" DEPTH - 2 1/2"
- **FOR HIGH ALTITUDE MODELS ADD HA SUFFIX**

HEATERS



UPC 686334	IVORY MODEL	UPC 686334	WHITE MODEL	WATTS	BTU's	VOLTS	DENSITY WATTS/FT.	HEATER LENGTH	WT	PIECES per SKID	LIST
104302	E2903-024S	104999	E2903-024SW	375	1275	120	187	24"	10 lbs.	37	
104319	F2903-024S	105002	F2903-024SW	375	1275	208	187				
104326	H2903-024S	105019	H2903-024SW	375 / 281	1275 / 955	240 / 208	187 / 140				
104333	G2903-024S	105026	G2903-024SW	375 / 281	1275 / 955	277 / 240	187 / 140				
104340	E2905-028S	105033	E2905-028SW	500	1706	120	215	28"	11 lbs.	39	
104357	F2905-028S	105040	F2905-028SW	500	1706	208	215				
104364	H2905-028S	105057	H2905-028SW	500 / 375	1706 / 1275	240 / 208	215 / 163				
104371	G2905-028S	105064	G2905-028SW	500 / 375	1706 / 1275	277 / 240	215 / 163				
104388	E2906-036S	105071	E2906-036SW	600	2040	120	200	36"	11.5 lbs.	45	
104395	F2906-036S	105088	F2906-036SW	600	2040	208	200				
104401	H2906-036S	105095	H2906-036SW	600 / 450	2040 / 1530	240 / 208	200 / 150				
104418	G2906-036S	105101	G2906-036SW	600 / 450	2040 / 1530	277 / 240	200 / 150				
104425	E2907-040S	105118	E2907-040SW	750	2550	120	227	40"	13 lbs.	46	
104432	F2907-040S	105125	F2907-040SW	750	2550	208	227				
104449	H2907-040S	105132	H2907-040SW	750 / 563	2550 / 1914	240 / 208	227 / 170				
104456	G2907-040S	105149	G2907-040SW	750 / 563	2550 / 1914	277 / 240	227 / 170				
104463	E2910-048S	105156	E2910-048SW	1000	3413	120	250	48"	14 lbs.	54	
104470	F2910-048S	105163	F2910-048SW	1000	3413	208	250				
104487	H2910-048S	105170	H2910-048SW	1000 / 750	3413 / 2550	240 / 208	250 / 187				
104494	G2910-048S	105187	G2910-048SW	1000 / 750	3413 / 2550	277 / 240	250 / 187				
104500	G2907-048S	105194	G2907-048SW	750	2550	277	187	60"	16 lbs.	64	
104517	E2912-060S	105200	E2912-060SW	1250	4250	120	250				
103008	F2912-060S	105217	F2912-060SW	1250	4250	208	250				
103015	H2912-060S	105224	H2912-060SW	1250 / 938	4250 / 3189	240 / 208	250 / 187				
103022	G2912-060S	105231	G2912-060SW	1250 / 938	4250 / 3189	277 / 240	250 / 187	72"	19 lbs.	73	
103039	G2909-060S	105248	G2909-060SW	938	3189	277	187				
103046	E2915-072S	105255	E2915-072SW	1500	5100	120	250				
103053	F2915-072S	105262	F2915-072SW	1500	5100	208	250				
103060	H2915-072S	105279	H2915-072SW	1500 / 1125	5100 / 3825	240 / 208	250 / 187	84"	22 lbs.	90	
103077	G2915-072S	105286	G2915-072SW	1500 / 1125	5100 / 3825	277 / 240	250 / 187				
103084	G2911-072S	105293	G2911-072SW	1125	3825	277	187				
103091	F2917-084S	105309	F2917-084SW	1750	5950	208	250				
103107	H2917-084S	105316	H2917-084SW	1750 / 1313	5950 / 4464	240 / 208	250 / 187	96"	25 lbs.	93	
103114	G2917-084S	105323	G2917-084SW	1750 / 1313	5950 / 4464	277 / 240	250 / 187				
103121	G2913-084S	105330	G2913-084SW	1313	4464	277	187				
103138	F2920-096S	105347	F2920-096SW	2000	6826	208	250				
103145	H2920-096S	105354	H2920-096SW	2000 / 1500	6826 / 5100	240 / 208	250 / 187	120"	31 lbs.	118	
103152	G2920-096S	105361	G2920-096SW	2000 / 1500	6826 / 5100	277 / 240	250 / 187				
103169	G2915-096S	105378	G2915-096SW	1500	5100	277	187				
103213	F2925-120S	105422	F2925-120SW	2500	8532	208	250				
103220	H2925-120S	105439	H2925-120SW	2500 / 1875	8532 / 6375	240 / 208	250 / 187	120"	31 lbs.	118	
103237	G2925-120S	105446	G2925-120SW	2500 / 1875	8532 / 6375	277 / 240	250 / 187				
103244	G2918-120S	105453	G2918-120SW	1875	6375	277	187				

ELECTRIC BASEBOARD CONVECTION HEATERS

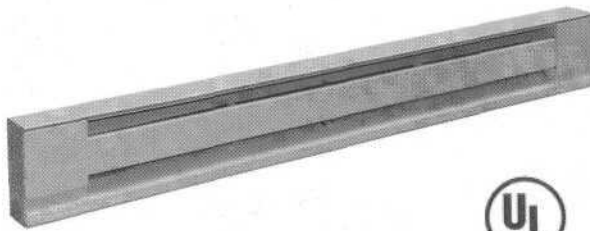

- Available in white or ivory with steel rod heating element and aluminum fins
- Powder coated 22ga. steel front with 20 ga. junction boxes located on each end of the heater - junction boxes contain quick connect cable clamps and 6" ground lead wires
- Over-temperature thermal limit extends entire length of heated area
- A full length wireway provided along the back of the heater - optional wireway covers are available
- Heater can be mounted to the wall by using the key hole knockouts every 4" at the back of the heater
- Optional built-in thermostats install in the junction box covers
- HEIGHT - 6" DEPTH - 2 1/2"
- **FOR HIGH ALTITUDE MODELS ADD HA SUFFIX**

UPC 686334	IVORY MODEL	UPC 686334	WHITE MODEL	WATTS	BTU's	VOLTS	DENSITY WATTS/FT.	HEATER LENGTH	WT.	PIECES per SKID	LIST
104302	DS1A03-024	104999	DS1A03-024W	375	1275	120	187	24"	10 lbs.	37	
104319	DS8A03-024	105002	DS8A03-024W	375	1275	208	187				
104326	DS2D03-024	105019	DS2D03-024W	375 / 281	1275 / 955	240 / 208	187 / 140				
104333	DS7D03-024	105026	DS7D03-024W	375 / 281	1275 / 955	277 / 240	187 / 140	28"	11 lbs.	39	
104340	DS1A05-028	105033	DS1A05-028W	500	1706	120	215				
104357	DS1A05-028	105040	DS8A05-028W	500	1706	208	215				
104364	DS1A05-028	105057	DS2A05-028W	500 / 375	1706 / 1275	240 / 208	215 / 163				
104371	DS1A05-028	105064	DS7A05-028W	500 / 375	1706 / 1275	277 / 240	215 / 163				
104388	DS1A06-036	105071	DS1A06-036W	600	2040	120	200	36"	11.5 lbs.	45	
104395	DS8A06-036	105088	DS8A06-036W	600	2040	208	200				
104401	DS2D06-036	105095	DS2D06-036W	600 / 450	2040 / 1530	240 / 208	200 / 150				
104418	DS7D06-036	105101	DS7D06-036W	600 / 450	2040 / 1530	277 / 240	200 / 150				
104425	DS1A07-040	105118	DS1A07-040W	750	2550	120	227	40"	13 lbs.	46	
104432	DS8A07-040	105125	DS8A07-040W	750	2550	208	227				
104449	DS2D07-040	105132	DS2D07-040W	750 / 563	2550 / 1914	240 / 208	227 / 170				
104456	DS7D07-040	105149	DS7D07-040W	750 / 563	2550 / 1914	277 / 240	227 / 170				
104463	DS1A10-048	105156	DS1A10-048W	1000	3413	120	250	48"	14 lbs.	54	
104470	DS8A10-048	105163	DS8A10-048W	1000	3413	208	250				
104487	DS2D10-048	105170	DS2D10-048W	1000 / 750	3413 / 2550	240 / 208	250 / 187				
104494	DS7D10-048	105187	DS7D10-048W	1000 / 750	3413 / 2550	277 / 240	250 / 187				
104500	DS7A07-048	105194	DS7A07-048W	750	2550	277	187				
104517	DS1A12-060	105200	DS1A12-060W	1250	4250	120	250	60"	16 lbs.	60	
103008	DS8A12-060	105217	DS8A12-060W	1250	4250	208	250				
103015	DS2D12-060	105224	DS2D12-060W	1250 / 938	4250 / 3189	240 / 208	250 / 187				
103022	DS7D12-060	105231	DS7D12-060W	1250 / 938	4250 / 3189	277 / 240	250 / 187				
103039	DS7A09-060	105248	DS7A09-060W	938	3189	277	187				
103046	DS1A15-072	105255	DS1A15-072W	1500	5100	120	250	72"	19 lbs.	73	
103053	DS8A15-072	105262	DS8A15-072W	1500	5100	208	250				
103060	DS2D15-072	105279	DS2D15-072W	1500 / 1125	5100 / 3825	240 / 208	250 / 187				
103077	DS7D15-072	105286	DS7D15-072W	1500 / 1125	5100 / 3825	277 / 240	250 / 187				
103084	DS7A11-072	105293	DS7A11-072W	1125	3825	277	187				
103091	DS8A17-084	105309	DS8A17-084W	1750	5950	208	250	84"	22 lbs.	90	
103107	DS2D17-084	105316	DS2D17-084W	1750 / 1313	5950 / 4464	240 / 208	250 / 187				
103114	DS7D17-084	105323	DS7D17-084W	1750 / 1313	5950 / 4464	277 / 240	250 / 187				
103121	DS7A13-084	105330	DS7A13-084W	1313	4464	277	187				
103138	DS8A20-096	105347	DS8A20-096W	2000	6826	208	250	96"	25 lbs.	93	
103145	DS2D20-096	105354	DS2D20-096W	2000 / 1500	6826 / 5100	240 / 208	250 / 187				
103152	DS7D20-096	105361	DS7D20-096W	2000 / 1500	6826 / 5100	277 / 240	250 / 187				
103169	DS7A20-096	105378	DS7A20-096W	1500	5100	277	187				
103213	DS8A25-120	105422	DS8A25-120W	2500	8532	208	250				
103220	DS2D25-120	105439	DS2D25-120W	2500 / 1875	8532 / 6375	240 / 208	250 / 187	120"	31 lbs.	118	
103237	DS7D25-120	105446	DS7D25-120W	2500 / 1875	8532 / 6375	277 / 240	250 / 187				
103244	DS7A18-120	105453	DS7A18-120W	1875	6375	277	187				

HEATERS

